


THE TRANE COMPANY  
LA CROSSE, WISCONSIN

B X13640308

G

RELAY DRIVE BOARD

SCALE  
NONE

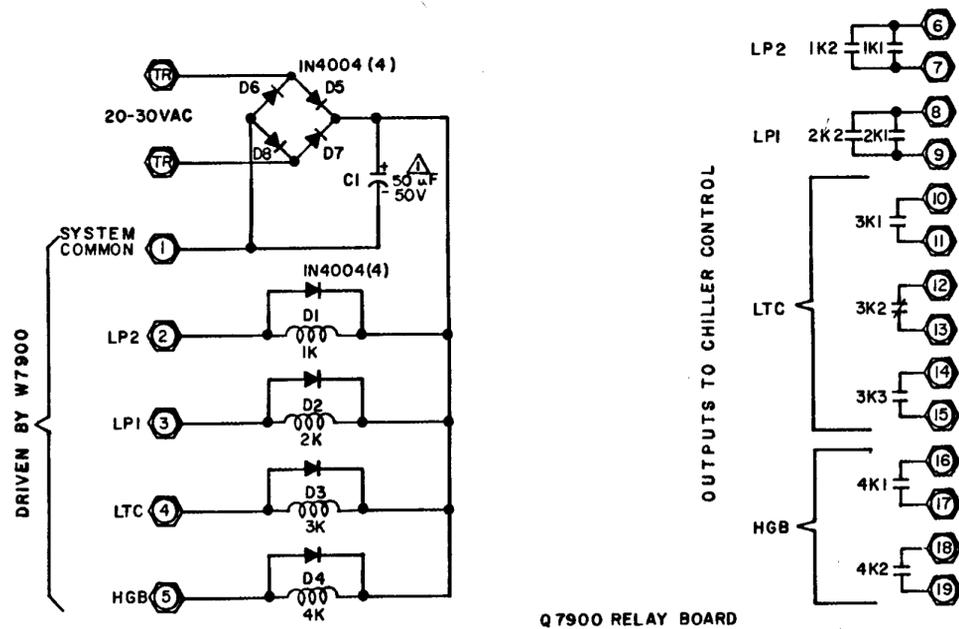

Q7900 RELAY BOARD


SPECIFICATION:

- INPUT: 20 TO 30 VAC, 60 HZ, 20 TO 26.4VAC, 50 HZ, 7VA @ 24 VAC.
- OUTPUT RELAYS:

CONTACT	VOLTAGE (V)	INRUSH (VA) MAX	RUNNING (VA) MAX
HGB 1&2 N.O.	120	250	25
LP 1&2 N.O.	120	1305	215
LTC 1&2 N.O.	120	300	300
LTC N.C.	120	120	120

- TERMINALS: ALL TERMINALS 1/4 INCH QUICK CONNECT
- AMBIENT TEMPERATURE LIMITS: -40°F TO +150°F
- UL & CSA RECOGNIZED
- MOUNTING: SURFACE MOUNT IN A PLASTIC SNAP-TRACK
- HUMIDITY LIMITS 90% RH MAX @ 90° NON-CONDENSING ENVIRONMENT.
- CORROSION 3 GAS TEST 100 PPM EACH CO<sub>2</sub>, SO<sub>2</sub>, H<sub>2</sub>S @ 100% RH
- RELAYS PERFORM SWITCHING FUNCTIONS IN A TRANE CHILLER CONTROL SYSTEM.

10 RELAYS MAY NOT BE IDENTIFIED ON PART

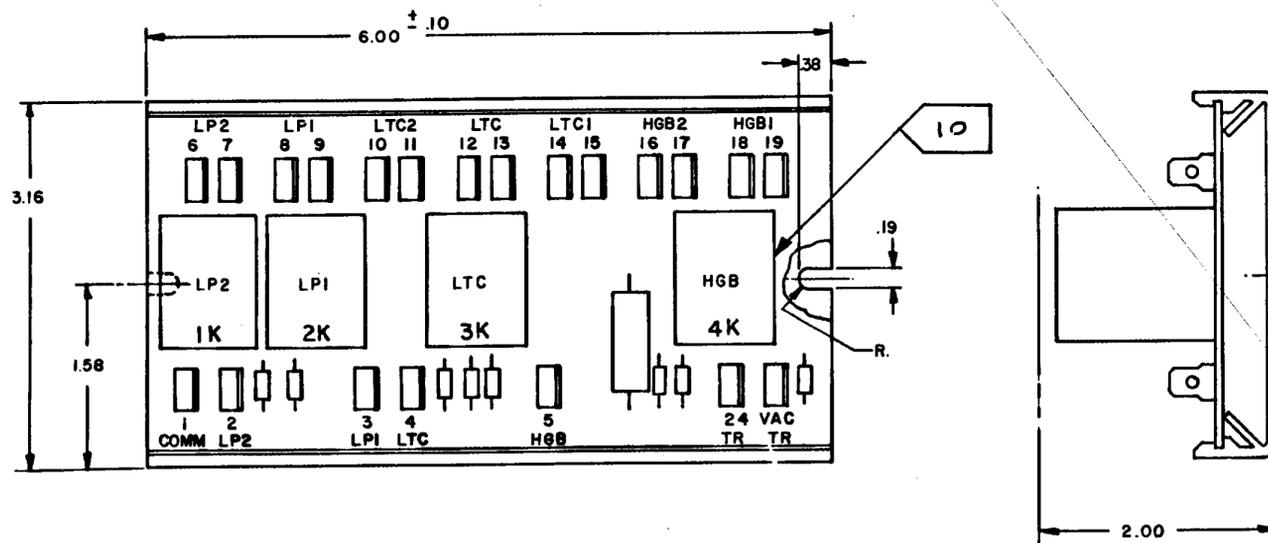

B X13640308